


Jungtis su kabeliu NEBV-H1G2-KN-5-N-LE2

Gaminio numeris: 566657

FESTO

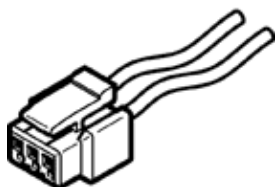

Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Montavimo pozicija	Bet koks
Produkto svoris	31 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Connection pattern H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	2 single wires
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampos lygis	0 ... 60 V
Leistina srovės apkrova prie 40°C	3 A
Kabelio ilgis	5 m
Kabelio priedas	Standartas
Kabelio skersmuo	1,3 mm
Kabelio struktūra	2x0,14
Nominalus laidininko skerspjūvis	0,14 mm ²
Laido galai	Cut off bluntly
Apsaugos klasė	IP40
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-5 ... 60 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Material housing	POM
Korpuso spalva	Juodas
Material electrical contact	Vario lydinys Galvanizuota
Material insulation	PVC