 



Paskirstytojas NEDY-L2R1-V1-M8G3-N-M12G4

Gaminio numeris: 8005311

FESTO

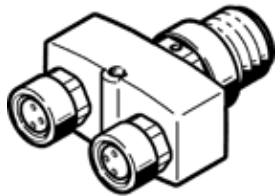

Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-101 EN 61076-2-104
Konstrukcija	Y-distributor without cable
Distributor type	2 to 1
Cable identification	Without inscription label holder
Montavimo tipas	With through-hole for M2 screw su priedais
Produkto svoris	20 g
Electrical connection 1, function	Controller side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 2, function	Field device side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	2x rozetė
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	3 A
Atsparumas smūgiams	0,8 kV
Apsaugos klasė	IP65 IP68 IP69K
Aplinkos temperatūra	-25 ... 85 °C
Note on ambient temperature	-10 ... 40 °C when mounted via through-hole
Saugojimo temperatūra	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno Free of phosphoric acid ester
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	PC TPE-U(PUR)
Korpuso spalva	Juodas
Material of union nut	Nikeliuotas varis
Material seals	NBR
Material electrical contact	Gold-plated copper alloy
Material threaded sleeve	Nikeliuotas varis