


surface light SBAL-C6-A-NR

Gaminio numeris: 8031160
Nebetiekiamas produktas

FESTO

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

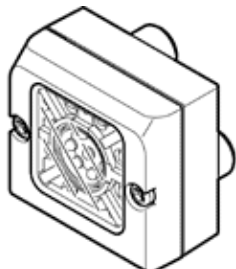

Tech. Duomenys

Savybės	Reikšmė
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvumus in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Leidimas	RCM Mark
Veikimo nuotolis	100 - 300 mm
Lighting type	Panel light
Šviesos tipas	Infraraudonieji LED Clear
Wavelength	860 nm
Elektrinis pajungimas	12-kontaktų 2x M12 Kištukas
Trigger level	Level 10 V ... UB
Nominali darbinė nuolatinė įtampa	24 V
Leistini įtampos svyravimai	+/- 10 %
Liekamoji pulsacija	10 %
Current consumption during continuous operation	90 mA
Current consumption during flash operation	100 mA
Maximum number of devices connectable in series	4
Apsaugotas nuo poliariškumo pakeitimo	visoms elektrinėms jungtims
Ambient temperature during continuous operation	0 ... 50 °C
Ambient temperature during flash operation	0 ... 50 °C
Saugojimo temperatūra	-20 ... 60 °C
Apsaugos klasė	IP67
PWIS conformity	VDMA24364-B2-L
Produkto svoris	60 g
Montavimo tipas	Fiksuotas "kregždės uodegos" formos griovelyje su priedais
Material housing	ABS- sustiprintas
Informacija	atitinka RoHS