


# ring light SBAL-C6-R-W-D

Gaminio numeris: 8031161  
Nebetiekiamas produktas

FESTO

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

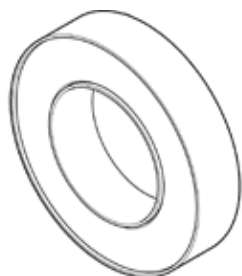

## Tech. Duomenys

Savybės	Reikšmė
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvumus in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Leidimas	RCM Mark
Veikimo nuotolis	100 - 300 mm
Lighting type	Ring light
Šviesos tipas	baltas LED Diffuse
Wavelength	410 - 750 nm
Elektrinis pajungimas	12-kontaktų 2x M12 Kištukas
Trigger level	Level 18 V ... UB
Nominali darbinė nuolatinė įtampa	24 V
Leistini įtampos svyravimai	+/- 5 %
Liekamoji pulsacija	5 %
Current consumption during continuous operation	390 mA
Current consumption during flash operation	390 mA
Maximum number of devices connectable in series	2
Apsaugotas nuo poliariškumo pakeitimo	visoms elektrinėms jungtims
Ambient temperature during continuous operation	0 ... 35 °C
Ambient temperature during flash operation	0 ... 50 °C
Saugojimo temperatūra	-20 ... 60 °C
Apsaugos klasė	IP67
PWIS conformity	VDMA24364-B2-L
Produkto svoris	150 g
Montavimo tipas	Su tvirtinimo kronšteinu
Material housing	Aliuminis anoduotas
Informacija	atitinka RoHS