


Paskirstytojas NEDY-

Gaminio numeris: 8032867

FESTO

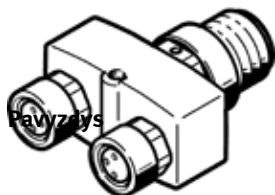

Tech. Duomenys

Pilnas duomenų lapas- atskiros reikšmės priklauso nuo Jūsų konfiguracijos.

Savybės	Reikšmė
Leidimas	RCM Mark
Distributor type	2 to 1
Parodyti kada pasiruošęs	LED žalias
Darbo režimo displėjus	LED geltonas
Signal status display	LED geltonas
Papildomos funkcijos	Laikymo srovės sumažėjimas
Cable identification	With inscription label holder Without inscription label holder
Montavimo tipas	With through-hole for M2 screw su priedais
Electrical connection 1, function	Controller side
Electrical connection 1, connection type	Kabelis Kištukas
Electrical connection 1, cable outlet	Tiesus Angled
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101 M8x1, A-coded to EN 61076-2-104 atviri laidai
Electrical connection 1, number of pins/wires	3 4
Electrical connection 2, function	Field device side
Electrical connection 2, connection type	2x rozetė 2x cable
Electrical connection 2, cable outlet	Tiesus Angled Rotatable
Electrical connection 2, connection technology	Connection pattern ZB, self-tapping screw Connection pattern ZC, self-tapping screw Connection pattern ZC, metric screw Connection pattern H Plug pattern type A to EN 175301-803 Plug pattern type B to EN 175301-803 Plug pattern type B to industry standard, 11 mm Plug pattern type C to EN 175301-803 Connection pattern type C to industry standard, 9.4 mm M12x1, A-coded in accordance with EN 61076-2-101 M8x1, A-coded to EN 61076-2-104 atviri laidai
Electrical connection 2, number of pins/wires	2 3 4 5
Nominalus DC įtampos lygis	0 ... 30 V
Nominalus AC įtampos lygis	0 ... 30 V

Savybės	Reikšmė
Leistina srovės apkrova prie 40°C	0,5 ... 4 A
Atsparumas smūgiams	0,8 kV
Cable length 1	0,3 ... 30 m
Cable length 2	0,3 ... 30 m
Kabelio priedas	Suitable for energy chains/robot applications
Nominalus laidininko skerspjūvis	0,14 mm ² 0,25 mm ²
Aplinkos temperatūra	-25 ... 85 °C
Note on ambient temperature	-10 ... 40 °C when mounted via through-hole
CE ženklas (žr. deklaraciją)	atitinka EU-EMV reikalvumus in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno Free of phosphoric acid ester
Užterštumo laipsnis	3
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	PA PC TPE-U(PUR)
Korpuso spalva	Juodas