


 
# Pajungimo kabelis

## NEBS-SM16G24-K-10-N-LE24

Gaminio numeris: 8048654  
Nebetiekiamas produktas

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

FESTO

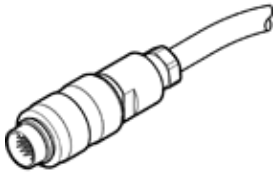

## Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-106
Atitinka standartus	DIN 47100
Cable identification	Without inscription label holder
Produkto svoris	1.490 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	M16x0,75
Electrical connection 1, number of pins/wires	24
Electrical connection 1, occupied pins/wires	24
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabelis
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	24
Nominalus DC įtampos lygis	30 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	500 V
Kabelio ilgis	10 m
Kabelio priedas	Standartas
Bending radius, fixed cable installation	> 51 mm
Bending radius, flexible cable installation	> 127,5 mm
Kabelio skersmuo	8,5 mm
Kabelio struktūra	25x0,14
Nominalus laidininko skerspjūvis	0,14 mm <sup>2</sup>
Laido galai	Cut off bluntly
Apsaugos klasė	IP67
Aplinkos temperatūra	-30 ... 70 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 70 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	1
Material cable sheath	PVC
Kabelio apvalkalo spalva	pilkas
Material housing	PA
Material screw-type lock	Nickel-plated brass
Material electrical contact	Brass, gold-plated
Material insulation	PVC