
 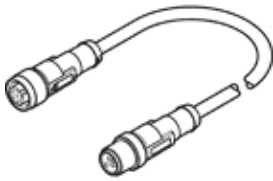


Adapteris

NEFC-M12G8-0.3-M12G5-LK

Gaminio numeris: 8080777

FESTO



Tech. Duomenys

| Savybės | Reikšmė |
|--|--|
| Paremtas standartu | EN 61076-2-101 |
| Protokolas | IO-Link |
| Leidimas | c UL us - Listed (OL) |
| Cable identification | Without inscription label holder |
| Produkto svoris | 30 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | apvalus |
| Electrical connection 1, connection type | Kištuko lizdas |
| Electrical connection 1, cable outlet | Tiesus |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 8 |
| Electrical connection 1, occupied pins/wires | 3 |
| Electrical connection 1, type of mounting | Screw lock |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, design | apvalus |
| Electrical connection 2, connection type | Kištukas |
| Electrical connection 2, cable outlet | Tiesus |
| Electrical connection 2, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 2, number of pins/wires | 5 |
| Electrical connection 2, occupied pins/wires | 3 |
| Electrical connection 2, type of mounting | Screw lock |
| Electrical connection 3, occupied pins/wires | 3 |
| Nominalus DC įtampos lygis | 0 ... 60 V |
| Nominalus AC įtampos lygis | 0 ... 48 V |
| Leistina srovės apkrova prie 40°C | 2 A |
| Atsparumas smūgiams | 0,8 kV |
| Shielding | Ne |
| Kabelio ilgis | 0,3 m |
| Kabelio priedas | Suitable for energy chains |
| Laido bandymo sąlygos | Bandymas pagal užklausimą |
| Bending radius, fixed cable installation | ≥ 26 mm |
| Bending radius, flexible cable installation | ≥ 26 mm |
| Kabelio skersmuo | 5,1 mm |
| Kabelio skersmens tolerancija | ± 0,2 mm |
| Kabelio struktūra | 5x0,34 |
| Nominalus laidininko skerspjūvis | 0,34 mm ² |
| Apsaugos klasė | IP65 IP67 |
| Note on degree of protection | Sumontuotas |
| Aplinkos temperatūra | -25 ... 90 °C |
| Aplinkos temperatūra esant lankščiai kabelių instaliacijai | -25 ... 90 °C |
| CE ženklas (žr. deklaraciją) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| Skyriaus sertifikatas | UL E474609 |
| PWIS conformity | VDMA24364-B2-L |
| Informacija | atitinka RoHS |

| Savybės | Reikšmė |
|-------------------------------|-------------------------------|
| Užterštumo laipsnis | 3 |
| Atsparumo korozijai klasė CRC | 2 - Moderate corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| Kabelio apvalkalo spalva | Silver-grey |
| Material housing | TPE-U(PUR) |
| Korpuso spalva | Juodas |
| Material screw-type lock | Nickel-plated die-cast zinc |
| Material seals | NBR |
| Material electrical contact | Žalvaris |
| Material insulation | PP |