


Line choke CAMF-C6-FD-C6-3A

Gaminio numeris: 8088930

★ Kernprogramm

FESTO

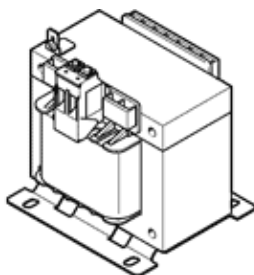

Tech. Duomenys

| Savybės | Reikšmė |
|--|--------------------------------------|
| Atsparumas trumpam jungimui | Ne |
| Leistina srovės apkrova prie 40°C | 6 A |
| Nominalus AC įtampos lygis | 0 ... 400 V |
| Nominali darbinė kintama įtampa | 400 V |
| Nominal inductance | 5,7 mH |
| Nominal inductance tolerance | 10 % |
| Linijos dažnis | 50 ... 60 Hz |
| Izoliacinė įtampa | 2.500 V |
| Leidimas | ENEC c UL - Recognized (OL) |
| CE ženklas (žr. deklaraciją) | in accordance with EU RoHS directive |
| PWIS conformity | VDMA24364 zone III |
| Saugojimo temperatūra | -10 ... 40 °C |
| Apsaugos klasė | IP00 |
| Aplinkos temperatūra | -10 ... 40 °C |
| Produkto svoris | 2.000 g |
| Montavimo tipas | Montavimo plokštė, prisukama |
| Informacija | atitinka RoHS |
| Montavimo pozicija | Horizontaliai |
| Electrical connection 1, function | Maitinimas |
| Electrical connection 1, connection type | Galinė juosta |
| Electrical connection 1, connection technology | Įsuktas terminalas |
| Electrical connection 1, number of pins/wires | 2 |
| Electrical connection 1, occupied pins/wires | 2 |
| Electrical connection 1, conductor cross section | 4 mm ² |
| Electrical connection 2, function | Maitinimas |
| Electrical connection 2, connection type | Galinė juosta |
| Electrical connection 2, connection technology | Įsuktas terminalas |
| Electrical connection 2, number of pins/wires | 2 |
| Electrical connection 2, occupied pins/wires | 2 |
| Electrical connection 2, conductor cross section | 4 mm ² |