 



Pajungimo kabelis NEBS-L1G4-K-1-N-M12G4

Gaminio numeris: 8091514

FESTO

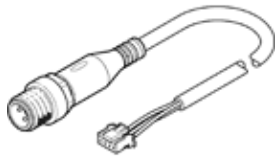

Tech. Duomenys

Savybės	Reikšmė
Cable identification	Without inscription label holder
Prijungimo dažnis	100
Produkto svoris	40 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuvo lizdas
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Connection pattern L1J
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, design	apvalus
Electrical connection 2, connection type	Kištukas
Electrical connection 2, cable outlet	Tiesus
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	4
Electrical connection 2, occupied pins/wires	4
Electrical connection 2, type of mounting	Screw-type lock with hex A/F 13 mm and longitudinal knurl
Nominalus DC įtampos lygis	0 ... 30 V
Leistina srovės apkrova prie 40°C	1 A
Atsparumas smūgiams	0,8 kV
Kabelio ilgis	1 m
Kabelio priedas	Standartas
Laido bandymo sąlygos	Bandymas pagal užklausimą
Bending radius, fixed cable installation	≥ 14 mm
Bending radius, flexible cable installation	≥ 46 mm
Kabelio skersmuo	4,5 mm
Kabelio skersmens tolerancija	± 0,1 mm
Kabelio struktūra	4x0,25
Nominalus laidininko skerspjūvis	0,25 mm ²
Apsaugos klasė	IP65 IP67 IP69K
Note on degree of protection	IP40 for plug connection pattern L1J Sumontuotas
Aplinkos temperatūra	-20 ... 60 °C
Aplinkos temperatūra esant lankščiai kabelių instaliacijai	-5 ... 60 °C
Saugojimo temperatūra	-20 ... 60 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS Be halogeno
Užterštumo laipsnis	2
Atsparumo korozijai klasė CRC	2 - Moderate corrosion stress

Savybės	Reikšmė
Material cable sheath	TPE-U(PUR)
Kabelio apvalkalo spalva	pilkas
Material housing	PA TPE-U(PUR)
Korpuso spalva	Juodas baltas
Material screw-type lock	Nickel-plated brass
Material electrical contact	Tin-plated bronze Brass, gold-plated
Material insulation	PP