


# Maitinimo tinklo filtras

## CAMF-C6-F-C16-11A

Gaminio numeris: 8096868

FESTO

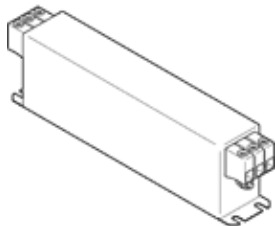

### Tech. Duomenys

Savybės	Reikšmė
Atsparumas trumpam jungimui	Ne
Leistina srovės apkrova prie 40°C	16 A
Nominalus AC įtampos lygis	0 ... 520 V
Linijos dažnis	0 ... 60 Hz
Izoliacinė įtampa	2.650 V
Matmenys B x L x H	45 mm x 235 mm x 70 mm
Leidimas	ENEC UL - Recognized (OL) c UL - Recognized (OL)
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
PWIS conformity	VDMA24364 zone III
Saugojimo temperatūra	-25 ... 100 °C
Apsaugos klasė	IP20
Aplinkos temperatūra	-25 ... 100 °C
Produkto svoris	800 g
Montavimo tipas	Montavimo plokštė, prisukama
Informacija	atitinka RoHS
Montavimo pozicija	Horizontaliai
Electrical connection 1, function	Maitinimas
Electrical connection 1, connection type	Galinė juosta
Electrical connection 1, connection technology	Įsuktas terminalas
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, conductor cross section	6 ... 10 mm <sup>2</sup>
Electrical connection 2, function	Maitinimas
Electrical connection 2, connection type	Galinė juosta
Electrical connection 2, connection technology	Įsuktas terminalas
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
Electrical connection 2, conductor cross section	6 ... 10 mm <sup>2</sup>