


pancake cylinder DPCB-N-...-1/2"- -

Gaminio numeris: 8104879

FESTO

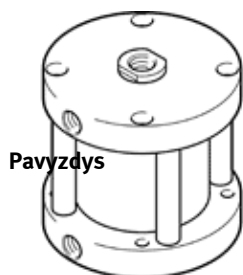

Pavyzdys

Tech. Duomenys

Pilnas duomenų lapas- atskiros reikšmės priklauso nuo Jūsų konfigūracijos.

Savybės	Reikšmė
Eiga	0,125 ... 4 "
Stūmoklio diametras	1/2"
Stūmoklio koto sriegis	8-32 UNC-2B 8-32 UNC-2A
Dempferiavimas	No cushioning P: elastiniai amortizavimo žiedai iš abiejų pusių Elastic cushioning rings/plates, at front Elastic cushioning rings/plates, at rear
Montavimo pozicija	Bet koks
Darbo režimas	dvipusio veikimo vienpusio veikimo stumiantys traukimo veiksmas
Koto galas	Išorinis sriegis Vidinis sriegis No thread
Konstrukcija	Stūmoklis Stūmoklio kotas Cilindro įvorė
Pozicijos atpažinimas	priartėjimo jutikliams
Variantai	Padidintas cheminis atsparumas Pailgintas cilindro kotas Mažos trinties Stūmoklio kotas į abi puses Through, hollow piston rod Temperatūros ribos -40 - 80 °C Scraper made of NBR Reinforced end cap Square lid shape With sensor mounting rail with sensor mounting rail rotated 90° with sensor mounting rail rotated 180° with sensor mounting rail rotated 270° Compressed air connection, rotated 90° Compressed air connection, rotated 180° Compressed air connection, rotated 270°
Apsauga nuo momento/kreipiamosios	Double piston rod with end plate Double piston rod with end plate rotated 90° Double piston rod with end plate with recess and through-hole Double piston rod with end plate with recess and through-hole rotated 90°
Darbinis slėgis	15 ... 150 Psi
Darbinė terpė	Suslėgto oro kokybė pagal ISO8573-1:2010 [7:4:4]
Reikalavimai darbinei ir valdymo terpei	Galima naudoti oro tepimą (pradėjus tepti, tolimesniam darbui oro tepimas būtinas)

Savybės	Reikšmė
PWIS conformity	VDMA24364 zone III
Aplinkos temperatūra	-25 ... 221 °F
Produkto svoris	1,15 ... 1,26 Pound
Montavimo tipas	Direct mounting on end cap via thread Direct mounting on bearing cap via thread Direct mounting on both sides via thread with swivelling rod eye on end cap rotated 90° with swivelling rod eye on end cap With through-hole on end cap With through-hole on bearing cap With through-hole on both sides With threaded flange on bearing cap With trunnion mounting on end cap With trunnion mounting on bearing cap su priedais Pasirenkamas
Pneumatinis pajungimas	Female thread 10-32 UNF-2B
Informacija	atitinka RoHS
Material cover	Aliuminio liejinys
Material of dynamic seals	FPM NBR
Material piston rod	high-alloy stainless steel, hard chrome plated
Material cylinder barrel	Reinforced composite material