


# Kištuko pagrindas NEFV-V14-XX4G3-T1G3

Gaminio numeris: 8109878

FESTO

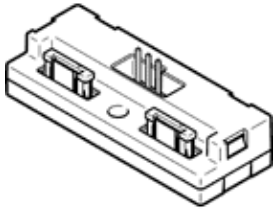

## Tech. Duomenys

Savybės	Reikšmė
Matmenys B x L x H	18,7 mm x 50 mm x 15,3 mm
Montavimo tipas	With through-hole for M3 screw
Cable outlet	Tiesus
Produkto svoris	6,8 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Kištuko lizdas
Electrical connection 1, connection technology	ZIF
Electrical connection 1, number of pins/wires	12
Electrical connection 1, occupied pins/wires	3
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, function	Field device side
Electrical connection 2, design	kampinis
Electrical connection 2, connection type	Kištuko lizdas
Electrical connection 2, connection technology	ZIF
Electrical connection 2, number of pins/wires	12
Electrical connection 2, occupied pins/wires	3
Electrical connection 2, type of mounting	Plug-in
Electrical connection 3, function	Controller side
Electrical connection 3, design	kampinis
Electrical connection 3, connection type	Kištukas
Electrical connection 3, connection technology	Festo-specific coding
Electrical connection 3, number of pins/wires	3
Electrical connection 3, occupied pins/wires	3
Electrical connection 3, type of mounting	Plug-in
Nominalus DC įtampos lygis	0 ... 310 V
Apsaugotas įžeminimas	Negalimas
Shielding	Ne
Apsaugos klasė	IP40
Note on degree of protection	Sumontuotas
Aplinkos temperatūra	-10 ... 60 °C
Saugojimo temperatūra	-40 ... 80 °C
CE ženklas (žr. deklaraciją)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	2
Atsparumo korozijai klasė CRC	1 - Low corrosion stress
Material housing	PA
Korpuso spalva	Juodas
Material electrical contact	Nickel-plated and gold-plated bronze