


# Pajungimo kabelis NEBV-HPG2-PN-0.3-N-LE2

Gaminio numeris: 8122832

FESTO

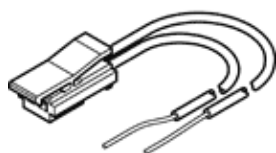

## Tech. Duomenys

Savybės	Reikšmė
Maksimalus elektromagnetinių ričių skaičius	1
Cable identification	Without inscription label holder
Montavimo pozicija	Bet koks
Produkto svoris	2 g
Electrical connection 1, function	Field device side Switching output
Electrical connection 1, design	kampinis
Electrical connection 1, connection type	Cable with socket
Electrical connection 1, cable outlet	Tiesus
Electrical connection 1, connection technology	Plug pattern HP
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Push-pull with interlock against unintentional pulling
Electrical connection 2, function	Maitinimas Controller side
Electrical connection 2, connection type	2 single wires
Electrical connection 2, connection technology	atviri laidai
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
Nominalus DC įtampos lygis	0 ... 24 V
Shielding	Ne
Nuoroda veikimui	Operate only with external power reduction
Kabelio ilgis	0,3 m
Kabelio priedas	Statiniam panaudojimui
Bending radius, fixed cable installation	≥ 11 mm
Kabelio skersmuo	0,96 mm
Apsaugos klasė	IP40
Aplinkos temperatūra	0 ... 50 °C
Saugojimo temperatūra	-20 ... 70 °C
PWIS conformity	VDMA24364 zone III
Informacija	atitinka RoHS
Atsparumo korozijai klasė CRC	0 - No corrosion stress
Material housing	PEEK
Korpuso spalva	pilkas
Material insulation	PVC