


Power supply plug NECL-S-L12G5-C2-Q10

Gaminio numeris: 8166791

FESTO

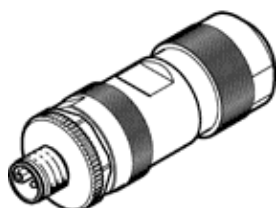

Tech. Duomenys

Savybės	Reikšmė
Paremtas standartu	EN 61076-2-111
Leidimas	c UL us - Recognized (OL)
Skyriaus sertifikatas	UL E474609
Montavimo tipas	Threaded
Cable outlet	Tiesus
Produkto svoris	42,89 g
Electrical connection 1, function	Maitinimas
Electrical connection 1, design	apvalus
Electrical connection 1, connection type	Kištukas
Electrical connection 1, connection technology	M12x1, L-coded to EN 61076-2-111
Electrical connection 1, number of pins/wires	5
Electrical connection 2, connection technology	Įsuktas terminalas
Nominalus DC įtampos lygis	0 ... 63 V
Nominali darbinė nuolatinė įtampa	63 V
Leistina srovės apkrova prie 40°C	16 A
Atsparumas smūgiams	1,5 kV
Leistinas kabelio skersmuo	8 - 13 mm for electrical connection 1
Nominalus laidininko skerspjūvis	≤ 2,5 mm ²
Nominal conductor cross section (AWG)	AWG14
Nuoroda į pajungimo skerspjūvį	Max. 1.5 mm ² /AWG16 when using wire end sleeves
Apsaugos klasė	IP65 IP67
Aplinkos temperatūra	-40 ... 105 °C
PWIS conformity	VDMA24364-B2-L
Informacija	atitinka RoHS
Užterštumo laipsnis	3
Atsparumo korozijai klasė CRC	1 - Low corrosion stress
Material housing	PA
Material screw-type lock	Nickel-plated die-cast zinc
Material electrical contact	Gold-plated copper alloy