


Ventuza burduf VASB-15-1/8-SI

Cod: 158977

FESTO

Inelul de etansare nu e inclus in completul de livrare.
produs retras. Livrabil pana in 2013.

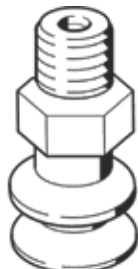

Fisa tehnica

Caracteristica	valoare
deschidere nominala	3 mm
diametru ventuza	15 mm
diametru efectiv ventuza	12 mm
structura constructiva	racord de vacuum deschis rotund, burduf incetrit de 1,5 ori
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
temperatura mediului	-40 ... 200 °C
forta de rupere la 70% vacuum	7,9 N
greutate produs	6 g
filet de fixare	G1/8
fixarea ventuzei	G 1/8
racord de vacuum	G1/8
duritate Shore	60 +/- 5
informatii referitoare la material pentru fus cu insurubare	aliaj maleabil aluminiu
indicatie material	contine substante cu LABS
informatii referitoare la material pentru ventuza	VMQ (silicon)