


Ventuza burduf VASB-75-1/4-SI

Cod: 160993

FESTO

Inelul de etansare nu e inclus in completul de livrare.
produs retras. Livrabil pana in 2012.

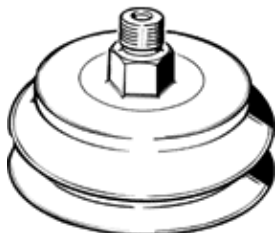

Fisa tehnica

Caracteristica	valoare
deschidere nominala	4 mm
diametru ventuza	75 mm
diametru efectiv ventuza	60 mm
structura constructiva	racord de vacuum deschis rotund, burduf incetrit de 1,5 ori
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
temperatura mediului	-40 ... 200 °C
forta de rupere la 70% vacuum	197 N
greutate produs	53 g
filet de fixare	G1/4
fixarea ventuzei	G 1/4
racord de vacuum	G1/4
duritate Shore	60 +/- 5
informatii referitoare la material pentru fus cu insurubare	aliaj maleabil aluminiu
indicatie material	contine substante cu LABS
informatii referitoare la material pentru ventuza	VMQ (silicon)