


# Ventuza burduf VASB-125-3/8-SI

Cod: 160995

FESTO

Inelul de etansare nu e inclus in completul de livrare.  
produs retras. Livrabil pana in 2013.

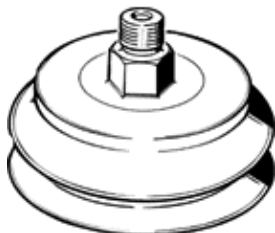

## Fisa tehnica

Caracteristica	valoare
deschidere nominala	7 mm
diametru ventuza	125 mm
diametru efectiv ventuza	105 mm
structura constructiva	racord de vacuum deschis rotund, burduf incretit de 1,5 ori
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
temperatura mediului	-40 ... 200 °C
forta de rupere la 70% vacuum	606 N
greutate produs	194 g
filet de fixare	G3/8
fixarea ventuzei	G3/8
racord de vacuum	G3/8
duritate Shore	60 +/- 5
informatii referitoare la material pentru fus cu insurubare	aliaj maleabil aluminiu
indicatie material	contine substante cu LABS
informatii referitoare la material pentru ventuza	VMQ (silicon)