


Interfata axa SPC-AIF-MTS

Cod: 170231

FESTO

Pentru Temposonics/AIFsau DGPI/L-AIF.

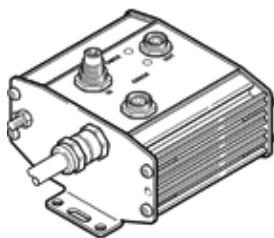

Fisa tehnica

Caracteristica	valoare
consum max. de curent ventil proportional	1,1 A
consum tipic de curent la interfata axei	200 mA
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV
rezistenta la socuri permanente, conform DIN/IEC 68 partea 2-82	testat dupa gradul de severitate 2
tip de protectie	IP65 conform IEC 60529
rezistenta la oscilatii conform DIN/IEC 68 partea 2-6	testat dupa gradul de severitate 2
temperatura mediului	0 ... 50 °C
greutate produs	300 g
racord electric ventil proportional	fisa design rotund M9 cu 7 poli
racord electric sistem de masurare a caili	cu 6 poli cablu cu fisa conform DIN 45322 design rotund
racord electric AIF IN	fisa design rotund M9 cu 5 poli
racord electric AIF AUT	doza design rotund M9 cu 5 poli
lungimea cablului	0,3 m