


# Ventuza VAS-10-M5-SI

Cod: 173442

FESTO

Inelul de etansare nu e inclus in completul de livrare.  
produs retras. Livrabil pana in 2012.

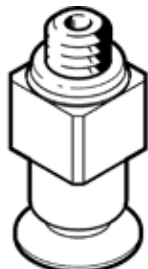

## Fisa tehnica

| Caracteristica  | valoare  |
|---|--|
| deschidere nominala   | 2 mm   |
| diametru ventuza  | 10 mm  |
| diametru efectiv ventuza                                    | 8 mm   |
| structura constructiva                                      | racord de vacuum deschis<br>rotund, standard             |
| mediu de operare  | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| temperatura mediului  | -40 ... 200 °C   |
| forta de rupere la 70% vacuum                               | 4,5 N  |
| greutate produs   | 3 g  |
| filet de fixare   | M5   |
| fixarea ventuzei  | M5   |
| racord de vacuum  | M5   |
| duritate Shore  | 60 +/- 5   |
| informatii referitoare la material pentru fus cu insurubare | aliaj maleabil aluminiu                                  |
| indicatie material  | contine substante cu LABS                                |
| informatii referitoare la material pentru ventuza           | VMQ (silicon)  |