


# Ventuza VAS-15-1/8-PUR-CT

Cod: 183512

FESTO

cu inel de etansare OL.

Tip iesit din fabricatie. Livrabil pana in 2010.

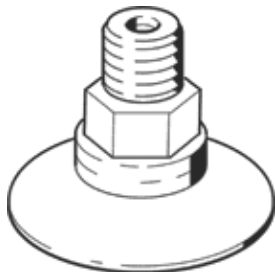

## Fisa tehnica

Caracteristica	valoare
deschidere nominala	3 mm
diametru ventuza	15 mm
diametru efectiv ventuza	12 mm
structura constructiva	racord de vacuum deschis rotund, standard
mediu de operare	aer atmosferic
temperatura mediului	-20 ... 60 °C
forta de rupere la 70% vacuum	7,9 N
filet de fixare	G1/8
fixarea ventuzei	G 1/8
racord de vacuum	G1/8
duritate Shore	62
informatii referitoare la material pentru fus cu insurubare	otel inoxidabil inalt aliat
indicatie material	Fara cupru si PTFE
informatii referitoare la material pentru ventuza	TPE-U(PU)