


Gripper cu ventuza ESG-4

Cod: 189168

FESTO

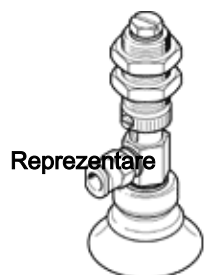

Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Diametru ventuza	4 mm
pozitie instalare	vertical
Caracteristici speciale	Antistatic
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 1
Forma ventuza	rotund plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-30 ... 200 °C
Racord de vacuum	M3 M10x1 QS-4 PK-3
Indicatie material	conform RoHS
Materialul ventuzei	BR FPM NBR PUR VMQ (silicon)