


Gripper cu ventuza ESG-80

Cod: 189178

FESTO

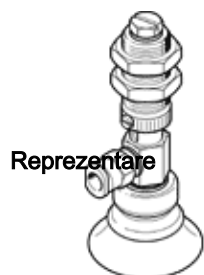

Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Diametru ventuza	80 mm
pozitie instalare	vertical
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 5
Forma ventuza	rotund plat rotund adanc rotund, foarte adanc Rotund, burduf 1,5 pliuri
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-30 ... 200 °C
Racord de vacuum	G1/8 G1/4
Indicatie material	conform RoHS
Materialul ventuzei	FPM NBR PUR VMQ (silicon) Vulkollan®