


Gripper cu ventuza ESG-10X30

Cod: 189188

FESTO

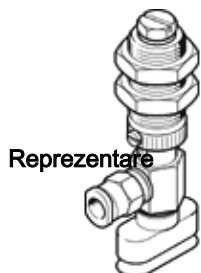

Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Marime ventuza	10x30 mm
pozitie instalare	vertical
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 4
Forma ventuza	Oval, plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-10 ... 70 °C
Racord de vacuum	M14x1 G1/8 QS-6 PK-4
Indicatie material	conform RoHS
Materialul ventuzei	NBR