


Ventuza VAS-55-1/4-PUR

Cod: 36139

FESTO

cu inel de etansare OL.

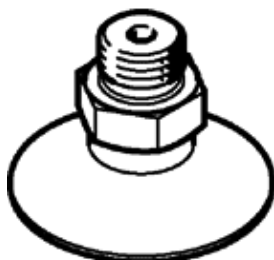

Fisa tehnica

| Caracteristica | valoare |
|---|--|
| deschidere nominala | 4 mm |
| diametru ventuza | 55 mm |
| diametru efectiv ventuza | 44 mm |
| structura constructiva | racord de vacuum deschis rotund, standard |
| mediu de operare | aer atmosferic |
| temperatura mediului | -20 ... 60 °C |
| forta de rupere la 70% vacuum | 106 N |
| filet de fixare | G1/4 |
| fixarea ventuzei | G 1/4 |
| racord de vacuum | G1/4 |
| duritate Shore | 62 |
| informatii referitoare la material pentru fus cu insurubare | zinc turnat sub presiune |
| informatii referitoare la material pentru ventuza | TPE-U(PU) |