 



Drosel cu amortizor de zgomot GRU-1/2

Cod: 4869

FESTO

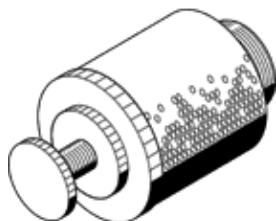

Fisa tehnica

Caracteristica	valoare
functiune de ventil	functiune drosel cu amortizor
racord pneumatic 1	G1/2
elemente de reglare	surub randalinat
tip fixare	insurubabil
debit nominal normal in directia droselului	2.500 l/min
presiune de operare	0 ... 10 bar
temperatura mediului	-10 ... 60 °C
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
temperatura mediului	-10 ... 60 °C
greutate produs	100 g
informatii referitoare la material pentru fus cu insurubare	POM
indicatie material	conform RoHS
informatii referitoare la material pentru surub de reglare	aliaj maleabil aluminiu