


# Interfata axa SPC-AIF-POT-LWG

Cod: 527496

FESTO

pentru potentiometru

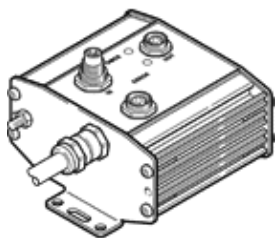

## Fisa tehnica

Caracteristica	valoare
consum max. de curent ventil proportional	1,1 A
consum tipic de curent la interfata axei	100 mA
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV
rezistenta la socuri permanente, conform DIN/IEC 68 partea 2-82	testat dupa gradul de severitate 2
tip de protectie	IP65 conform IEC 60529
rezistenta la oscilatii conform DIN/IEC 68 partea 2-6	testat dupa gradul de severitate 2
temperatura mediului	0 ... 50 °C
greutate produs	300 g
racord electric ventil proportional	fisa design rotund M9 cu 7 poli
racord electric sistem de masurare a caii	16 mm cu 4 poli cablu cu fisa design patrat
racord electric AIF IN	fisa design rotund M9 cu 5 poli
racord electric AIF AUT	doza design rotund M9 cu 5 poli
lungimea cablului	0,3 m