 



# Modul de ramificare MS4-FRM-1/8-Y

Cod: 529560

FESTO

cu releu de presiune fara indicare, debit de tranzit de la stanga la dreapta.

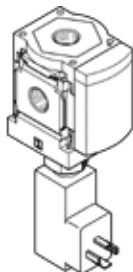

## Fisa tehnica

Caracteristica	valoare
pozitie instalare	oricare
structura constructiva	modul de ramificatie
presiune de operare	0 ... 12 bar
debit standard in directia principala de curgere 1->2	1.800 l/min
debit standard la iesirea superioara	1.600 l/min
debit standard la iesirea inferioara	1.700 l/min
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
clasa de rezistenta la coroziune KBK	2
temperatura de depozitare	-10 ... 60 °C
temperatura mediului	-10 ... 60 °C -10 ... 60 °C
greutate produs	405 g
racord pneumatic 1	G1/8
racord pneumatic 2	G1/8
racord pneumatic 3	G1/4
racord pneumatic 4	G1/4
indicatie material	Free of copper and PTFE conform RoHS
informatii referitoare la material pentru carcasa	aluminu turnat sub presiune