


Dopuri opturare QSC-F-8H

Cod: 533906

FESTO

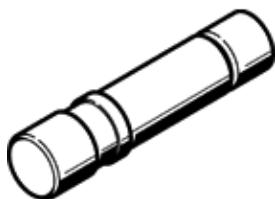

Fisa tehnica

Caracteristica	valoare
marime de fabricatie	standard
Operating pressure complete temperature range	-0,95 ... 16 bar
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
clasa de rezistenta la coroziune KBK	3
Food safety	to manufacturer's declaration
temperatura mediului	0 ... 150 °C
aprobare	Germanischer Lloyd
greutate produs	7,6 g
racord pneumatic 1	Racord de imbinare QS-8
indicatie material	conform RoHS
informatii referitoare la material pentru carcasa	alama cromat si nichelat
informatii referitoare la material pentru etansare filet	FPM
informatii referitoare la material pentru etansare furtun	FPM