


# bloc de baza CDVI5.0-GB8-DN

Cod: 535839

FESTO

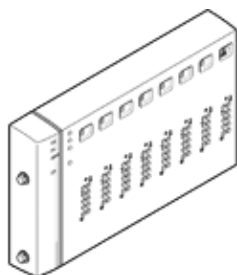

## Fisa tehnica

Caracteristica	valoare
lungime	244 mm
numarul max. de pozitii de ventile	8
clasa de rezistenta la coroziune KBK	3
aprobare	C-Tick
greutate produs	2.360 g
tip fixare	cu filet interior si bolt
racord deschidere pentru respiratie	G1/8
racord pneumatic 2	G1/8
racord pneumatic 4	G1/8
indicatie material	conform RoHS