


insula ventile CPA14-ASI-VI

Cod: 535848

FESTO

Typ 12, locas 14 mm.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

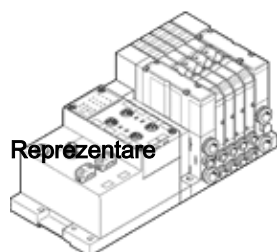

Reprezentare

Fisa tehnica

~ConfIndependentDatasheet

Caracteristica	valoare
functiune de ventil	2x3/2 deschis/inchis, monostabil 2x3/2 inchis, monostabil 2x3/2 deschis, monostabil 5/2 monostabil 5/2 bistabil 5/3 presurizat 5/3 exhaustat 5/3 inchis
debit nominal normal	600 l/min
presiune de operare	-0,9 ... 10 bar
racordare electrica	AS-Interface
numarul max. de pozitii de ventile	8
Nr.max.de zone de presiune	4
temperatura mediului	-5 ... 50 °C
Latime constructie	14 mm
tip de protectie	IP65
marimea ramei	14 mm
tip de actionare	electric
tip insula	12
structura constructiva	sertar cu piston
alimentare cu aer pilot	extern intern
structura insulei de ventile	modular si extensibil
afisarea pozitiei de comutare	LED
presiune de comanda	3 ... 8 bar
tensiune nominala de operare DC	24 V
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV
clasa de rezistenta la coroziune KBK	2
temperatura mediului	-5 ... 50 °C