

insula ventile CPA-SC-FB-VI


Cod: 538509

Produs in retragere de pe piata

cu conectare field-bus.

Type to be discontinued. Available until 2014. See Support Portal for alternative products.

FESTO

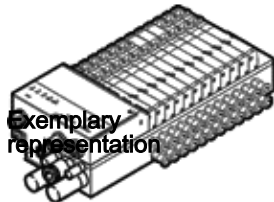

Fisa tehnica

Overall data sheet – Individual values depend upon your configuration.

Caracteristica	valoare
functiune de ventil	2x2/2 inchis/deschis, monostabil 2x3/2 inchis, monostabil 2x3/2 deschis, monostabil 3/2 inchis, monostabil 5/2 bistabil 5/2 monostabil 5/3 presurizat 5/3 exhaustat 5/3 inchis
Valve size	10 mm
Max. standard nominal flow rate	180 l/min bei 10 mm
presiune de operare	-0,9 ... 10 bar
racordare electrica	bus de camp
numarul max. de pozitii de ventile	24
Nr.max.de zone de presiune	2
Sistem electric de I/O	da
temperatura mediului	-5 ... 50 °C
Latime constructie	10 mm
tip de protectie	IP40
aprobare	c UL us - Recognized (OL)
deschidere nominala	2,5 mm
functiune de evacuare a aerului	nedroselizabil
tip de actionare	electric
tip insula	82
structura constructiva	sertar cu piston
alimentare cu aer pilot	extern intern
structura insulei de ventile	raster fix
afisarea pozitiei de comutare	LED
presiune de comanda	3 ... 8 bar
compatibilitate la vacuum	da
tensiune nominala de operare DC	24 V
oscilatii admisibile ale tensiunii	+/- 10 %
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Simbol CE (vezi declaratia de conformitate)	conform directivei europene EMV
clasa de rezistenta la coroziune KBK	1
temperatura mediului	-5 ... 50 °C
mediu de comanda	Compressed air in accordance with ISO8573-1:2010 [7:4:4]