


Bobina

VACN-N-K11-1-0.5-U4-M

Cod: 541665

FESTO

Conductor conectare cu tub izolator, 24 V DC.

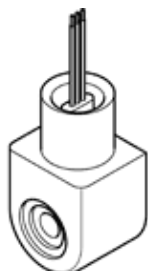

Fisa tehnica

Caracteristica	valoare
caracteristica bobina	24 V DC: 4.5 W
oscilatii admisibile ale tensiunii	+/- 10 %
Certificat ATEX in afara UE	NEC 500 Class I, Div. 1
clasa de rezistenta la coroziune KBK	1
tip de protectie	IP65
temperatura mediului	-20 ... 60 °C
lungimea cablului	0,5 m
indicatie material	conform RoHS