


**Cuplaj**  
**KSE-40-66-D08-D11**  
Cod: 550997

**FESTO**

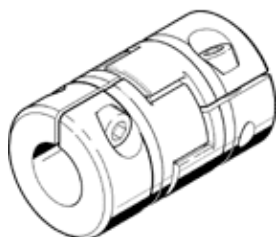

**Fisa tehnica**

| <b>Caracteristica</b>          | <b>valoare</b>         |
|--------------------------------|------------------------|
| diametru de prindere 1         | 8 mm                   |
| diametru de prindere 2         | 11 mm                  |
| marime de fabricatie           | 40                     |
| pozitie instalare              | oricare                |
| numarul max. de turatii        | 6.500 1/min            |
| momentul de inertie a masei    | 42,3 kgmm <sup>2</sup> |
| moment de rotatie transferabil | 17 Nm                  |
| greutate produs                | 139 g                  |
| indicatie material             | conform RoHS           |