


# Racord rapid T QST-F-G1/2-14

Cod: 570447

FESTO

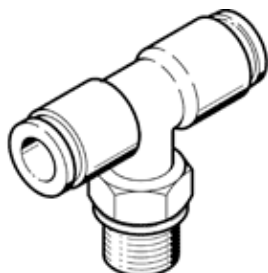

## Fisa tehnica

Caracteristica	valoare
marime de fabricatie	standard
deschidere nominala	11,5 mm
tip de etansare la fusul cu insurubare	inel de etansare
structura constructiva	principiu Push-Pull
Operating pressure complete temperature range	-0,95 ... 16 bar
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
clasa de rezistenta la coroziune KBK	3
Food safety	to manufacturer's declaration
temperatura mediului	0 ... 150 °C
aprobare	Germanischer Lloyd
cuplul maxim de pornire	40 Nm
greutate produs	100 g
racord pneumatic 1	G1/2
racord pneumatic 2	For tubing outside diameter 14 mm
indicatie material	conform RoHS
informatii referitoare la material pentru carcasa	alama cromat si nichelat
informatii referitoare la material pentru etansare filet	FPM
informatii referitoare la material pentru etansare furtun	FPM