


# Kit axial EAMM-A-N38-70AA

Cod: 8063576

FESTO

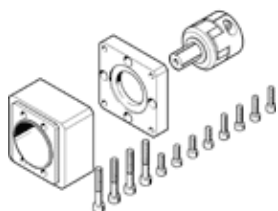

## Fisa tehnica

Caracteristica	valoare
pozitie instalare	Oricare
Conformitatea PWIS	VDMA24364-B2-L
Temperatura de depozitare	-25 ... 60 °C
Umiditatea relativa a aerului	0 - 95 %
Tip de protectie	IP40
Temperatura mediului	-10 ... 60 °C
Moment de rotatie transferabil	12,5 Nm
Greutate produs	615 g
Cod interfata actuator	N38
Cod interfata, intrare motor	70AA 70AB
Indicatie material	conform RoHS