


Reductor EMGA-80-A-G5-80P

Cod: 8085347

FESTO

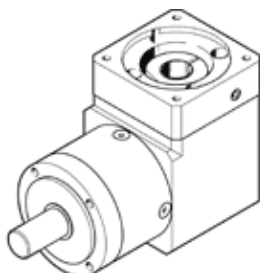

Fisa tehnica

Caracteristica	valoare
Transmisie flansa	80 mm
Motor cu flansa	80 mm
Joc de rasucire	0,22 deg
tipul reductorului	Reductor in unghi drept
Raport de transmisie	5:1
Viteza maxima de intrare	7.000 1/min
Temperatura de operare reductor	-25 ... 90 °C
Conformitatea PWIS	VDMA24364-B2-L
Tip de protectie	IP54
Cuplu de actionare continua	67 Nm
Momentul de inertie al angrenajului	1,017 kgcm ²
Cuplu maxim iesire	107 Nm
Eficienta maxima	95 %
rigiditate la torsiune	4,8 Nm/arcmin
Greutate produs	4.300 g
Interfata reductor arbore de iesire	80G
Interfata reductor arbore de antrenare	80P
Indicatie material	conform RoHS