


# Bobina VACC-S18-120-K4-27-NE4ME

Cod: 8118261

FESTO

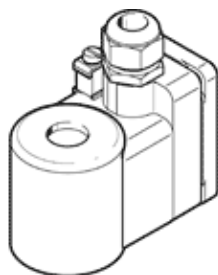

## Fisa tehnica

| Caracteristica                                 | valoare                               |
|--|---------------------------------------|
| tip de actionare                               | electric                              |
| pozitie instalare                              | Oricare                               |
| Afisarea pozitiei de comutare                  | nu                                    |
| Durata de anclansare                           | 100 %                                 |
| Clasa izolatie                                 | H                                     |
| Caracteristica bobina                          | 60 V DC: 12 W                         |
| Oscilatii admisibile ale tensiunii             | -15 % / +10 %                         |
| Certificat ATEX in afara UE                    | EPL Db (CN)<br>EPL Gb (CN)            |
| Departament eliberare certificate              | GYJ17.1237X                           |
| Tip gaz cu protectie la explozie si aprindere  | Ex e mb IIC T4 Gb                     |
| Tip praf cu protectie la aprindere si explozie | Ex tD A21 IP66 T120°C                 |
| Protectie la explozie temperatura ambientala   | T4,T120°C:-25°C<=Ta<=+40°C            |
| Conformitatea PWIS                             | VDMA24364-zona III                    |
| Tip de protectie                               | IP66                                  |
| Greutate produs                                | 580 g                                 |
| Conectare electrica                            | Cutie terminal, cablu filetat M20x1.5 |
| Indicatie material                             | conform RoHS                          |