


Bobina VACC-S13-18-K4-1UF-NE4ME

Cod: 8118332

FESTO

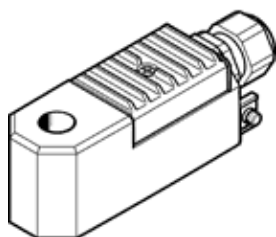

Fisa tehnica

Caracteristica	valoare
tip de actionare	electric
pozitie instalare	Oricare
Afisarea pozitiei de comutare	nu
Protectie interna	Siguranta de protectie
Durata de anclansare	100 %
Clasa izolatie	H
Caracteristica bobina	24 V DC: 1.8 W 24 V AC: 40/65 Hz, putere 1.8 VA
Oscilatii admisibile ale tensiunii	-15 % / +10 %
Certificat ATEX in afara UE	EPL Db (CN) EPL Gb (CN)
Departament eliberare certificate	GYJ17.1235X
Tip gaz cu protectie la explozie si aprindere	Ex e mb IIC T4/T5/T6 Gb
Tip praf cu protectie la aprindere si explozie	ExtDA21 IP65T130°C/T95°C/T85°C
Protectie la explozie temperatura ambientala	T4,T130°C: -30°C ≤ Ta ≤ +60°C T5,T95°C: -30°C ≤ Ta ≤ +60°C T6,T85°C: -30°C ≤ Ta ≤ +50°C
Conformitatea PWIS	VDMA24364-zona III
Tip de protectie	IP65
Greutate produs	330 g
Conectare electrica	Cutie terminal, cablu filetat M20x1.5
Indicatie material	conform RoHS