 



Ventil VOFC-L-M52-M-FN14-FN

Cod: 8122930

FESTO

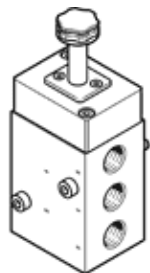

Fisa tehnica

| Caracteristica | valoare |
|---|---|
| Presiune de operare Mpa | 0,25 ... 0,8 MPa |
| presiune de operare | 2,5 ... 8 bar |
| Tip de protectie | IP65 |
| Safety Integrity Level (SIL) = Nivel de siguranta integrata | Produsul poate fi utilizat in SRP/CS pana la SIL 2 (cerere ridicata) Produsul poate fi utilizat in SRP/CS pana la SIL 2 Low Demand |
| Clasa de rezistenta la coroziune KBK | 4 - Rezistenta foarte ridicata la coroziune |
| Conformitatea PWIS | VDMA24364-zona III |
| Indicatie material | conform RoHS |