 



Ventil VOFC-L-M52-M-N14-FN

Cod: 8122931

FESTO

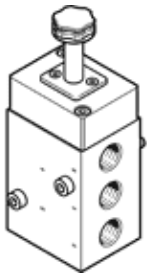

Fisa tehnica

Caracteristica	valoare
Presiune de operare Mpa	0,25 ... 0,8 MPa
presiune de operare	2,5 ... 8 bar
Tip de protectie	IP65
Safety Integrity Level (SIL) = Nivel de siguranta integrata	Produsul poate fi utilizat in SRP/CS pana la SIL 2 (cerere ridicata) Produsul poate fi utilizat in SRP/CS pana la SIL 2 Low Demand
Clasa de rezistenta la coroziune KBK	4 - Rezistenta foarte ridicata la coroziune
Conformitatea PWIS	VDMA24364-zona III
Indicatie material	conform RoHS