


# Reductor EMGA-60-A-G20-60P

Cod: 8141740

FESTO

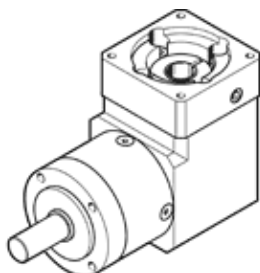

## Fisa tehnica

Caracteristica	valoare
Transmisie flansa	60 mm
Motor cu flansa	60 mm
Joc de rasucire	0,3 deg
tipul reductorului	Reductor in unghi drept
Raport de transmisie	20:1
Viteza maxima de intrare	13.000 1/min
Temperatura de operare reductor	-25 ... 90 °C
Conformitatea PWIS	VDMA24364-B2-L
Tip de protectie	IP54
Cuplu de actionare continua	44 Nm
Momentul de inertie al angrenajului	0,256 kgcm <sup>2</sup>
Cuplu maxim iesire	70 Nm
Eficienta maxima	92 %
rigiditate la torsiune	2 Nm/arcmin
Greutate produs	1.900 g
Interfata reductor arbore de iesire	60G
Interfata reductor arbore de antrenare	60P
Indicatie material	conform RoHS