


## Set axial EAMM-A-D50-80P-G2

Numar piesa: 8197489

**FESTO**

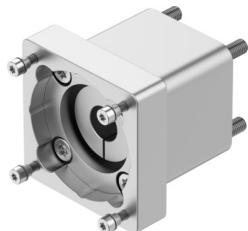

### Fisa de date

| Caracteristica               | Valoare                |
|------------------------------|------------------------|
| Lungime nominala             | 77.5 mm                |
| Pozitie de instalare         | orice                  |
| Turatie max.                 | 6000 1/min             |
| Conformitatea LABS           | VDMA24364-B2-L         |
| Temperatura de depozitare    | -25 °C...60 °C         |
| Umiditate relativa           | 0 - 95 %               |
| Tip de protectie             | IP40                   |
| Temperatura ambianta         | -10 °C...60 °C         |
| Momentul de inertie al masei | 34.8 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 21 Nm                  |
| Greutate produs              | 810 g                  |
| Cod de interfata actuator    | D50                    |
| Codul interfetei motor In    | 80P<br>80PA<br>80RA    |
| Nota privind materialele     | Conform RoHS           |