


Axial kit EAMM-A-X22-42A

Numar piesa: 8210057

FESTO

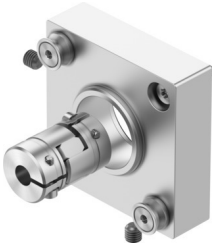

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	0.95 Nm
Greutate produs	60 g
Cod de interfata actuator	X22
Codul interfetei motor In	42A
Nota privind materialele	Conform RoHS