


Ventuza cu conector OGVM-50-A-N-RA

Numar piesa: 8213234

FESTO

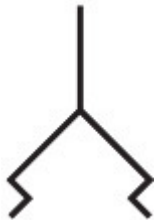

Fisa de date

Caracteristica	Valoare
Ventuza de compensare a inaltimii	11.5 mm
Raza min. a piesei de prelucrat	35 mm
Latimea nominala	7 mm
Diametrul ventuzei	50 mm
Volum de aspiratie	15 cm ³
Pozitie de conectare	sus
Pozitie de instalare	orice
Forma de ventuza	burduf rotund de 1,5 ori
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Presiunea nominala de functionare	-60 kPa -0.6 bar -8.7 psi
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7::-]
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-A1/A2-L
Temperatura ambianta	-20 °C...80 °C
Fora de mentinere la presiune de lucru nominala	90 N
Fora transversala la presiunea de lucru nominala	72 N
Greutate produs	48 g
Tipul de montare	prin racordul de vid
Racord de vacuum	Adaptor dreptunghiular RA
Culoare	negru
Duritate Shore	60 +/- 5
Material pivot de insurubare	Aliaj de aluminiu forjat
Nota privind materialele	Conform RoHS
Material ventuze	NBR