 



# Motorski vod

## NEBM-SF1W31-EH-2.6-Q15N-LE14

Broj artikla: 5213343

FESTO

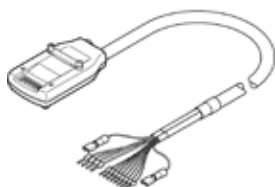

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	DIN 47100
Cable identification	Without inscription label holder
Frekvencija priključivanja	30
Težina proizvoda	770 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Angled
Electrical connection 1, note about the cable outlet	90°
Electrical connection 1, connection technology	Connection pattern F1
Electrical connection 1, number of pins/wires	31
Electrical connection 1, occupied pins/wires	31
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	14
Electrical connection 2, occupied pins/wires	14
Područje pogonskog napona DC	0 ... 50 V
Nazivni pogonski napon DC	24 V
Strujna opteretivost kod 40°C	0,5 A
Čvrstoća na udarno naprezanje	0,25 kV
Dužina kabla	2,6 m
Svojstvo kabla	Suitable for energy chains
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 49,5 mm
Bending radius, flexible cable installation	≥ 74,25 mm
Prečnik kabla	9,9 mm
Odstupanje prečnika kabla	± 0,2 mm
Struktura kabla	1x(6x0,35)+2x(4x0,15)
Nazivni presek provodnika	0,35 mm <sup>2</sup> 0,15 mm <sup>2</sup>
Krajevi žica	Završetak žice
Mehanička zaštita	IP20
Note on degree of protection	u montiranom stanju
Temperatura okoline	-20 ... 75 °C
Temperatura okoline kod pokretnog postepenja kablova	-5 ... 70 °C
Temperatura ležaja	-25 ... 55 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Materijal - napomena	RoHS komfornost
Stepen zagađenja	1
Klasa korozione otpornosti KBK	1 - Low corrosion stress
Material cable sheath	TPE-U(PUR)
Boja izolacije	crno
Material housing	PA
Boja kućišta	crno
Material electrical contact	Legura bakra, kalajisana