

# Vod enkodera

 

## NEBM-M12W8-E-5-N-S1G15

Broj artikla: 550318

Komponenta koja će prestati da se proizvodi

[odgovara za servomotor EMMS-AS-...](#)

**FESTO**

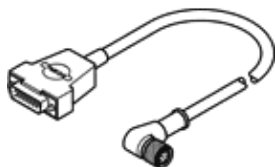

## Tehnički podaci

| Svojstvo                                             | Vrednost                                             |
|------------------------------------------------------|------------------------------------------------------|
| Odgovara standardu                                   | EN 61984                                             |
| Cable identification                                 | Without inscription label holder                     |
| Electrical connection 1, function                    | Field device side                                    |
| Electrical connection 1, design                      | okruglo                                              |
| Electrical connection 1, connection type             | Utičnica                                             |
| Electrical connection 1, cable outlet                | Angled                                               |
| Electrical connection 1, connection technology       | M12x1, A-coded in accordance with EN 61076-2-101     |
| Electrical connection 1, number of pins/wires        | 8                                                    |
| Electrical connection 1, occupied pins/wires         | 8                                                    |
| Electrical connection 2, function                    | Controller side                                      |
| Electrical connection 2, design                      | ugaono                                               |
| Electrical connection 2, connection type             | Utikači                                              |
| Electrical connection 2, cable outlet                | Ravno                                                |
| Electrical connection 2, connection technology       | Sub-D                                                |
| Electrical connection 2, number of pins/wires        | 15                                                   |
| Electrical connection 2, occupied pins/wires         | 8                                                    |
| Područje pogonskog napona DC                         | 0 ... 30 V                                           |
| Nazivni pogonski napon DC                            | 24 V                                                 |
| Područje pogonskog napona AC                         | 0 ... 30 V                                           |
| Nazivni pogonski napon AC                            | 24 V                                                 |
| Strujna opteretivost kod 40°C                        | 3 A                                                  |
| Note on acceptable current load at 40°C              | 2 A for 0.14 mm <sup>2</sup>                         |
| Čvrstoća na udarno naprezanje                        | 0,5 kV                                               |
| Dužina kabla                                         | 5 m                                                  |
| Svojstvo kabla                                       | prikladno za energetski lanac                        |
| Bending radius, fixed cable installation             | ≥ 20 mm                                              |
| Bending radius, flexible cable installation          | ≥ 75 mm                                              |
| Prečnik kabla                                        | 6 mm                                                 |
| Struktura kabla                                      | 1x4x0,14+4x0,34<br>zaslonjeno                        |
| Nazivni presek provodnika                            | 0,14 mm <sup>2</sup><br>0,34 mm <sup>2</sup>         |
| Mehanička zaštita                                    | IP65                                                 |
| Note on degree of protection                         | IP30 for plug connector Sub-D<br>u montiranom stanju |
| Temperatura okoline                                  | -40 ... 80 °C                                        |
| Temperatura okoline kod pokretnog postepenja kablova | -10 ... 80 °C                                        |
| CE znak (vidi izjavu o usklađenosti)                 | in accordance with EU RoHS directive                 |
| UKCA marking (see declaration of conformity)         | To UK RoHS instructions                              |
| PWIS conformity                                      | VDMA24364-B2-L                                       |
| Materijal - napomena                                 | RoHS komfornost                                      |
| Stepen zagađenja                                     | 3                                                    |
| Material cable sheath                                | TPE-U(PUR)                                           |