


插入式穿板接頭

QSS-12-F

料號: 130644

FESTO

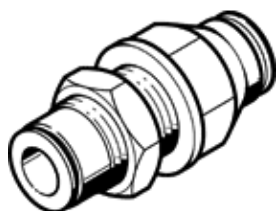

技術參數

特性	值
尺寸	標準
額定尺寸	7.5 mm
裝配位置	任何
設計	Bulkhead
容器尺寸	10
設計結構	推/拉原理
Operating pressure for entire temperature range	-0.095 ... 0.6 MPa
操作壓力的完整溫度範圍	-0.95 ... 6 bar
Operating pressure for entire temperature range	-13.775 ... 87 psi
Temperature-dependent operating pressure	-0.095 ... 1.4 MPa
溫度取決於操作壓力	-0.95 ... 14 bar
Temperature-dependent operating pressure	-13.775 ... 203 psi
Maritime classification	see certificate
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
注意: 操作和嚮導介質	潤滑操作可行
耐腐蝕等級 CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
環境溫度	-10 ... 80 °C
產品重量	105 g
氣壓連接, 氣口 1	For tubing outside diameter 12 mm
氣壓連接, 氣口 2	For tubing outside diameter 12 mm
釋放環的顏色	藍色
材料備註	符合 RoHS
Material housing	鍍鎳黃銅
Material release ring	POM
Material nut	鍍鎳黃銅
Material of tubing seal	NBR
Material of tube retaining claw	高合金鋼, 耐腐蝕