


插入連接件

QS-V0-4

料號: 132890

FESTO

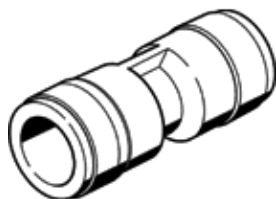

技術參數

| 特性 | 值 |
|---|--|
| 尺寸 | 標準 |
| 額定尺寸 | 2.8 mm |
| Material fire test | UL94 V-0 (housing) UL94 V-0 (releasing ring) |
| 設計 | 直式結構 |
| 容器尺寸 | 1 |
| 設計結構 | 推/拉原理 |
| Operating pressure for entire temperature range | -0.095 ... 1 MPa |
| 操作壓力的完整溫度範圍 | -0.95 ... 10 bar |
| Operating pressure for entire temperature range | -13.775 ... 145 psi |
| 操作壓力注意事項 | Water: max. 0.6 MPa at max. 50°C |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice) |
| 注意: 操作和嚮導介質 | 潤滑操作可行 |
| 耐腐蝕等級 CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| 環境溫度 | 0 ... 60 °C |
| 產品重量 | 6.1 g |
| 氣壓連接, 氣口 1 | For tubing outside diameter 4 mm |
| 氣壓連接, 氣口 2 | For tubing outside diameter 4 mm |
| 釋放環的顏色 | 黑色 |
| 材料備註 | 符合 RoHS |
| Material housing | PBT |
| Material of tubing seal | NBR |
| Material of tube retaining claw | 高合金鋼, 耐腐蝕 黃銅 |