

圓形氣壓缸 DSAS-20- -PPV-A

 

料號: 171742
將停止供貨的產品

端蓋具擺動軸承

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

FESTO

代表範例

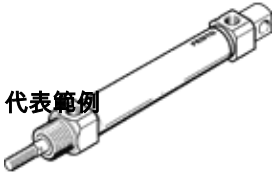

技術參數

特性	值
行程	1 ... 320 mm
活塞直徑	20 mm
緩衝	PPV: 兩端具可調的氣緩衝
操作壓力	1 ... 10 bar
操作模式	雙動
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:4:4]
注意: 操作和嚮導介質	潤滑操作可行 (隨後需要進一步操作)
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
環境溫度	-20 ... 80 °C
緩衝長度	17 mm
Theoretical force at 0.6 MPa (6 bar, 87 psi), retracting	158.3 N
Theoretical force at 0.6 MPa (6 bar, 87 psi), advance	188.5 N
0 mm行程時的運動質量	79 g
每 10 mm 行程的附加質量係數	3.9 g
0 mm行程時的基本重量	138 g
每 10 mm 行程所增加的重量	7.2 g
氣壓連接	M20x1,5
Material cover	鍛造鋁合金
Material seals	NBR TPE-U(PU)
Material housing	高合金鋼, 耐腐蝕
Material piston rod	高合金鋼, 耐腐蝕