


塑料氣管

PLN-10X1,5-NT

料號: 193406

FESTO

具高度耐化學腐蝕和耐水解能力

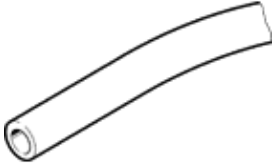

技術參數

| 特性 | 值 |
|--|--|
| 外徑 | 10 mm |
| 與流量相關的彎曲半徑 | 57 mm |
| 內徑 | 7 mm |
| 最小彎曲半徑 | 22 mm |
| Temperature-dependent operating pressure | -0.095 ... 1.4 MPa |
| 溫度取決於操作壓力 | -0.95 ... 14 bar |
| Temperature-dependent operating pressure | -13.775 ... 203 psi |
| 操作壓力注意事項 | Water: max. 0.6 MPa at 0 - 50 °C |
| 授權 | TÜV |
| 認證核發部門 | B 013277 0506 00 |
| 操作介質 | 壓縮空氣符合 ISO8573-1:2010 [7:-:-] Water (liquid, free of ice) |
| PWIS conformity | VDMA24364-B2-L |
| 無塵室等級 | This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly. |
| Food-safe | See Supplementary material information |
| 環境溫度 | -30 ... 80 °C |
| 產品重量視長度而定 | 0.0375 kg/m |
| 氣壓連接 | For push-in connector outside diameter 10 mm |
| 顏色 | 中性 |
| 材料備註 | 符合 RoHS |
| Material tubing | PE |